


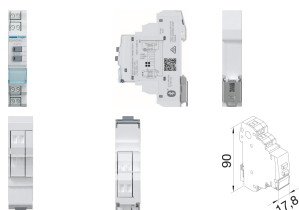

EGN100AU



## Multi-function time switch 1 channel bluetooth

### Technical properties

#### Voltage

Nominal voltage	230 - 240 V
-----------------	-------------

#### Frequency

Frequency	50 - 60 Hz
-----------	------------

#### Power

230 V incandescent and halogen lamp	2300 W
-------------------------------------	--------

#### Lighting

Max. load fluorescent lamp in series	1000 W
--------------------------------------	--------

#### Functions

Power reserve in years	10 y
With network synchronisation	Yes
With quartz synchronisation	Yes

#### Equipment

Accuracy per day	0,25 s
With impulse programme	Yes
Number of channels	1

#### Connection

Type of contacts	1x changeover
Cross-section flexible conductor	0.2 - 2.5 mm <sup>2</sup>
Cross-section rigid conductor	0.2 - 4 mm <sup>2</sup>

#### Settings

Daily programme	Yes
Weekly programme	Yes
Annual programme	Yes

#### Use conditions

Operating temperature	-5 - +45 °C
-----------------------	-------------

#### Texts

Type of connection	With screw terminal
--------------------	---------------------

#### Dimensions

Height	90 mm
Width	17,80 mm

