




47236089

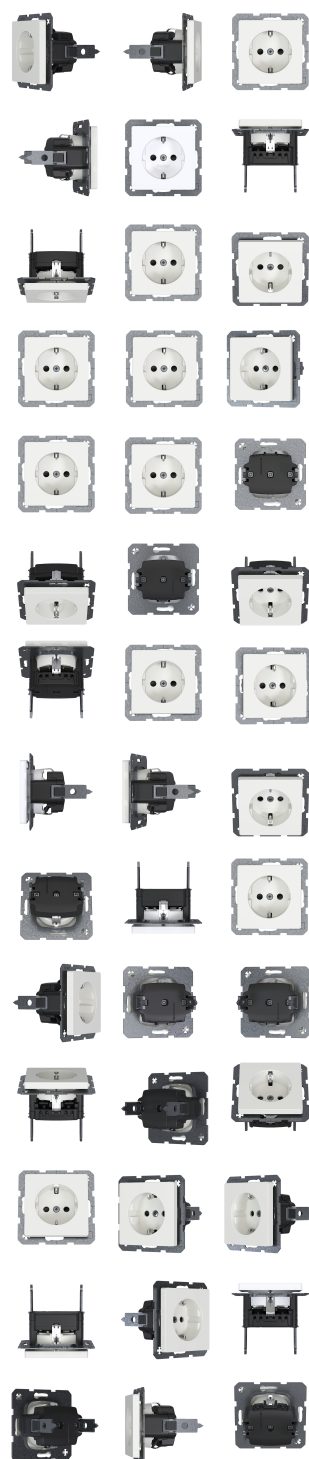

## SCHUKO soc. out., enhncd contact prot., Q.x, p. white velvety

### Technical properties

#### Architecture

Design according to DIN 49440

#### Configuration

Number of modules 1

#### Main electrical features

Nominal voltage 250 V

Rated voltage 250 V AC

Frequency 50/60 Hz

Rated current 16 A

#### Electric current

Rated current 16 A

#### Dimensions

Insertion depth 32 mm

Installation depth, flush-mounted boxes 31 mm

#### Cover, door

Cover Central cover plate

#### Materials

Colour of design line polar white

Colour white

RAL colour RAL 9010 - Pure white

Surface appearance velvety

Metallic colour No

#### Installation, mounting

Installation mode with spreader claws

#### Connection

Connection terminals according to IEC 60884-1

Connection terminals according to VDE 0620-1

Type of connection with plug-in terminals

#### Use

Differentiation characteristic 2 - Sales with enhanced touch protection

#### Safety



IK protection code against mecanical impacts		02
Protection		Enhanced contact protection
With enhanced contact protection		Yes
<b>Identification</b>		
Main design line		Berker Q.1/Q.3/Q.7/Q.9
Secondary design line(s)		Berker Q.1 ; Berker Q.3 ; Berker Q.7 ; Berker Q.9