


TXA215

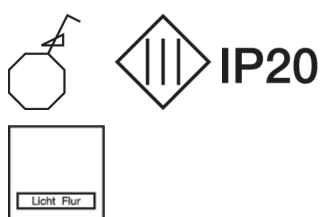

## Dimmer 1 channel 1000W

### Technical properties

#### Architecture

Bus system	KNX
Fixing mode	Din-Rail

#### Configuration

Number of modules	6
-------------------	---

#### Controls and indicators

Indicator lamp	yes
----------------	-----

#### Main electrical features

Frequency	50/60 Hz
Rated current	4.3 A

#### Voltage

System supply voltage	30V DC via bus
-----------------------	----------------

#### Power

Incandescent bulb power	20 / 1000 W
Total power loss under IN	10 W
Power of the variator	20 / 1000 W

#### Materials

Colour	stone grey
--------	------------

#### Connection

Type of load	universal
--------------	-----------

#### Equipment

Type of dimmer	universal
Bidirectional radio frequency	No

#### Safety

Protection index IP	IP20
---------------------	------

#### Use conditions

Operating temperature	0...45 °C
Storage/transport temperature	-20...70 °C