


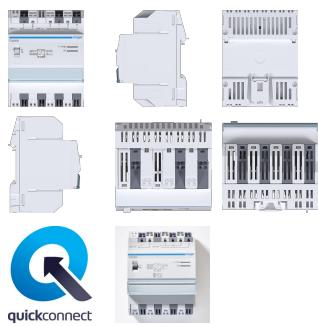

TGA200



Power supply 24 V DC 1A

Technical properties

Electric current

Output current	1,000 mA
----------------	----------

Functions

Output voltage adjusted	Yes
-------------------------	-----

Frequency

Frequency	50 - 60 Hz
-----------	------------

Power

Power consumption standby	0.20 W
---------------------------	--------

Capacity

Number of modules	4
-------------------	---

Voltage

Output voltage	24 - 24 V
----------------	-----------

Use conditions

Operating temperature	0 - 45 °C
-----------------------	-----------