


TXA610D

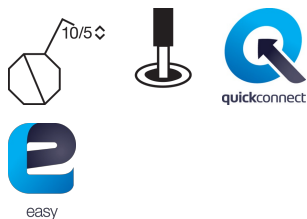

Output module 10x 16A (C)/230V~, KNX

Technical properties

Connectivity

With bus system KNX	Yes
With bus system KNX radio	No

Settings

Supported configuration mode	ETS, easy
------------------------------	-----------

Dimensions

Height	90 mm
Number of width units	6

Materials

Colour	Grey
--------	------

Equipment

Radio frequency bidirectional	No
With switch for manual switch	Yes

Electric current

Rated current	16 A
Bus current consumption while idle	4 mA

Frequency

Frequency	50 - 60 Hz
-----------	------------

Power

Output power	2,300 W
230 V incandescent and halogen lamp	2,300 W

Voltage

Rated operational voltage U _e	230 - 230 V
System supply voltage	30 V DC Via bus
Operating voltage over bus	21 - 32 V

Safety

Ingress Protection (IP) class	IP20
-------------------------------	------

Use conditions

Operating temperature	-5 - 45 °C
-----------------------	------------

Texts

Function	With safety functions e.g. for wind, rain, alarm, With positioning function for blind and lamella position, With sun shade function
Type of connection	With quickconnect plug-in terminals
Connection	
Cross-section rigid conductor	0.75 - 2.5 mm ²
Cross-section flexible conductor	0.75 - 2.5 mm ²