


**Top & bottom, quadro evo, 1000x400 mm**

**Technical properties**

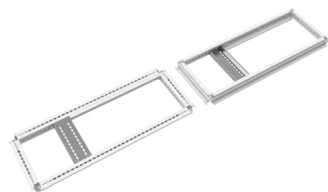

FN024EW

**Dimensions**

|                             |         |
|-----------------------------|---------|
| Insertion depth             | 400 mm  |
| Depth of installed product  | 400 mm  |
| Height of installed product | 50 mm   |
| Width of installed product  | 1000 mm |
| Built-in width              | 1000 mm |

**Materials**

|                    |                       |
|--------------------|-----------------------|
| RAL colour         | RAL 9010 - Pure white |
| Surface appearance | glossy                |

**Installation, mounting**

|                          |    |
|--------------------------|----|
| Suitable for outdoor use | No |
| With cable entry         | No |

**Standards**

|                         |               |
|-------------------------|---------------|
| Approvals               | EN 61439-1/-2 |
| European directive WEEE | not concerned |

**Safety**

|   |     |
|---|-----|
| IK protection code against mechanical impacts | 10  |
| REACH conform                                 | No  |
| RoHS conform                                  | Yes |
| Halogen free                                  | Yes |