


HTG411H

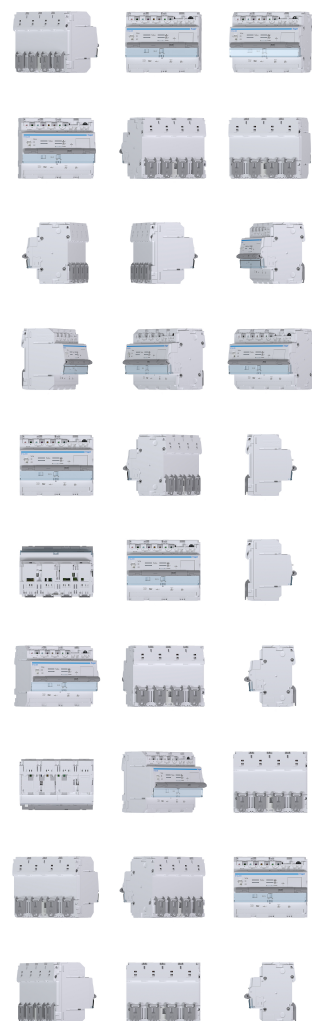

Multi energy data logger & server + micro SD card

Technical properties

Configuration

Number of modules	6
-------------------	---

Controls and indicators

With LED indication	Yes
---------------------	-----

Connectivity

Protocol	TCP/IP
Other bus systems	other
Model System interface/media gateway for bus system	Ethernet interface

Main electrical features

Type of supply voltage	DC
------------------------	----

Voltage

Operating voltage	24 V
-------------------	------

Power

Power consumption	7 VA
-------------------	------

Equipment

Number of digital inputs	2
Number of USB interfaces	2
Demounting protection	No
Bidirectional radio frequency	No
Radio interface	No
IR interface	No
Updateable	Yes
Visualization	No
Web-Server	Yes
Number of analogical inputs	2

Standards

European directive RoHS	voluntary compliance
-------------------------	----------------------

Safety

REACH conform	No
Halogen free	No

Use conditions

Operating temperature	-25...70 °C
Storage/transport temperature	-55...85 °C