


HTG411H

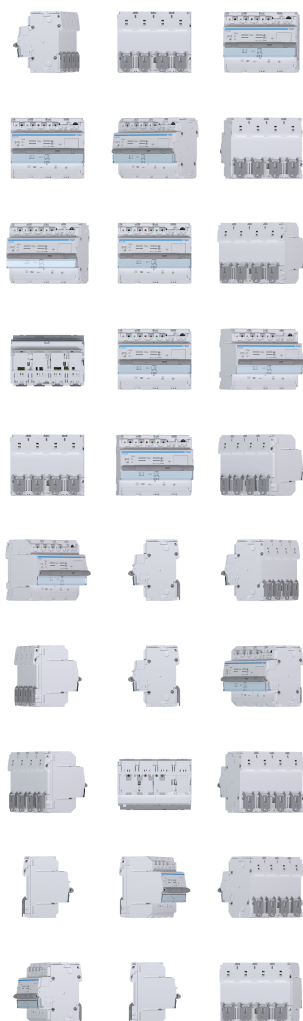

Multi energy data logger & server + micro SD card

Technical properties

Configuration

Number of modules 6

Controls and indicators

With LED indication Yes

Connectivity

Protocol TCP/IP

Other bus systems other

Model System interface/media gateway for bus system Ethernet interface

Main electrical features

Type of supply voltage DC

Voltage

Operating voltage 24 V

Power

Power consumption 7 VA

Equipment

Number of digital inputs 2

Number of USB interfaces 2

Demounting protection No

Bidirectional radio frequency No

Radio interface No

IR interface No

Updateable Yes

Visualization No

Web-Server Yes

Number of analogical inputs 2

Standards

European directive RoHS voluntary compliance

Safety

REACH conform No

Halogen free No

Use conditions

Operating temperature	-25...70 °C
Storage/transport temperature	-55...85 °C
