




SL200801

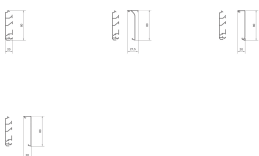

**Trunking base SL20080 black**

**Technical properties**

**Dimensions**

Trunking height	80 mm
Length	2000 mm
Trunking width	20 mm

**Capacity**

Maximum number of cables (Ø 11 mm, 50% fill)	6
Cable capacity 11mm D e.g. NYM 3 x 1.5mm <sup>2</sup> 2nd chamber	2 Part
Cable capacity 11mm D e.g. NYM 3 x 1.5mm <sup>2</sup> 3rd chamber	4 Part

**Materials**

Material group	plastic
Type of surface treatment	Other

**Cable**

Number of wires 1,5 mm <sup>2</sup> - 40% filling degree	72
Number of wires 2,5 mm <sup>2</sup> - 40% filling degree	46

**Equipment**

Number of fix dividers	2
Compartment quantity	3

**Standards**

Approvals	CE
European directive RoHs	voluntary compliance

**Safety**

REACH conform	Yes
RoHS conform	Yes
Halogen free	No
Impact strength	IK07

**Use conditions**

Operating temperature	5...60 °C
-----------------------	-----------

**temperatur**

Ambient temperature	5...60 °C
---------------------	-----------