


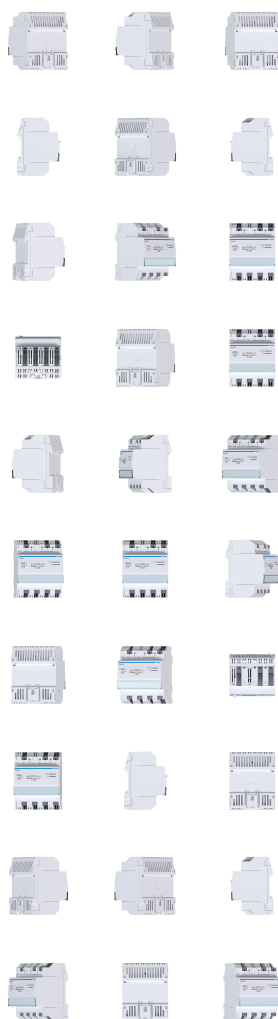

TGA200



Power supply 24 V DC 1A

Technical properties

Architecture

Bus system EIB

Configuration

Number of modules 4

Main electrical features

Frequency 50/60 Hz

Voltage

Output voltage 24 V DC

Output voltage 24 V

Filtered output voltage 24V +/- 5%

Electric current

Output current 1 A

Dimensions

Depth of installed product 64 mm

Height of installed product 90 mm

Width of installed product 72 mm

Power

Current consumption 150 mA

Power consumed 16 VA

Power consumption (standby) 0.2 W

Total power loss under IN 15 W

Measurement

Voltage measurement range 22.8 to 25.2 V

Materials

RAL colour RAL 7035 - Light grey

Installation, mounting

Modular version Yes

Suitable for front mounting No

Connection

Connection cross-sect. flexible conductor 0,75 / 2,5mm²

Connection cross-sect. rigid cable 0,75 / 2.5mm²

| | |
|--|-------------------------------------|
| Type of connection | with QuickConnect plug-in terminals |
| Type of connection | Quickconnect |
| Equipment | |
| Short-circuit protected | Yes |
| Use | |
| Differentiation characteristic 1 - Sales | with labelling field |
| Safety | |
| REACH conform | No |
| RoHS conform | Yes |
| Halogen free | No |