


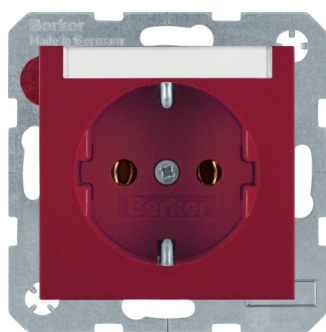

47508902

SCHUKO soc. out., S.1/B.3/B.7, red glossy

Technical characteristics

Architecture

Design	according to DIN 49440
Fixing mode	flush-mounting

Configuration

Number of modules	1
-------------------	---

Main electrical features

Nominal voltage	250 V
Rated voltage	250 V AC
Frequency	50/60 Hz
Rated current	16 A

Electric current

Rated current	16 A
---------------	------

Dimensions

Insertion depth	32 mm
Installation depth, flush-mounted boxes	31 mm

Cover, door

Cover	Central cover plate
-------	---------------------

Materials

Design lines special colours	red
Colour	red
Colour	red
RAL colour	RAL 3003 - Ruby red
Material	duroplastic
Metallic colour	No

Installation, mounting

Installation mode	with spreader claws
-------------------	---------------------

Connection

Connection terminals	according to IEC 60884-1
Connection terminals	according to VDE 0620-1
Type of connection	with plug-in terminals

Use

Differentiation characteristic 1 - Sales	with labelling field
--	----------------------

Safety		
IK protection code against mechanical impacts		02
Protection index IP		IP20
REACH conform		Yes
RoHS conform		Yes
Protection	without enhanced contact protection	
With enhanced contact protection		No

Identification

Main design line	Berker S.1/B.3/B.7	
Secondary design line(s)	Berker S.1, Berker B.3, Berker B.7	

Instructions

Information text	Insert colour-coded. 1140. Labelling field height designed for 6 mm P-touch strips.	
------------------	---	--