




SL200801

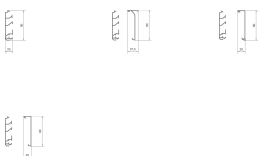

**Trunking base SL20080 black**

**Technical characteristics**

**Dimensions**

|                 |         |
|-----------------|---------|
| Trunking height | 80 mm   |
| Length          | 2000 mm |
| Trunking width  | 20 mm   |

**Capacity**

|   |        |
|---|--------|
| Maximum number of cables (Ø 11 mm, 50% fill)                      | 6      |
| Cable capacity 11mm D e.g. NYM 3 x 1.5mm <sup>2</sup> 2nd chamber | 2 Part |
| Cable capacity 11mm D e.g. NYM 3 x 1.5mm <sup>2</sup> 3rd chamber | 4 Part |

**Materials**

|                           |         |
|---------------------------|---------|
| Colour                    | black   |
| Material group            | plastic |
| Type of surface treatment | Other   |

**Cable**

|  |    |
|--|----|
| Number of wires 1,5 mm <sup>2</sup> - 40% filling degree | 72 |
| Number of wires 2,5 mm <sup>2</sup> - 40% filling degree | 46 |

**Equipment**

|                        |   |
|------------------------|---|
| Number of fix dividers | 2 |
| Compartment quantity   | 3 |

**Standards**

|                         |                      |
|-------------------------|----------------------|
| Approvals               | CE                   |
| European directive RoHs | voluntary compliance |

**Safety**

|                 |      |
|-----------------|------|
| REACH conform   | Yes  |
| RoHS conform    | Yes  |
| Halogen free    | No   |
| Impact strength | IK07 |

**Use conditions**

|                       |           |
|-----------------------|-----------|
| Operating temperature | 5...60 °C |
|-----------------------|-----------|

**temperatur**

|                     |           |
|---------------------|-----------|
| Ambient temperature | 5...60 °C |
|---------------------|-----------|