




SL200801

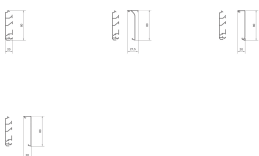

Trunking base SL20080 black

Technical characteristics

Dimensions

Trunking height	80 mm
Length	2000 mm
Trunking width	20 mm

Capacity

Maximum number of cables (Ø 11 mm, 50% fill)	6
Cable capacity 11mm D e.g. NYM 3 x 1.5mm ² 2nd chamber	2 Part
Cable capacity 11mm D e.g. NYM 3 x 1.5mm ² 3rd chamber	4 Part

Materials

Colour	black
Material group	plastic
Type of surface treatment	Other

Cable

Number of wires 1,5 mm ² - 40% filling degree	72
Number of wires 2,5 mm ² - 40% filling degree	46

Equipment

Number of fix dividers	2
Compartment quantity	3

Standards

Approvals	CE
European directive RoHs	voluntary compliance

Safety

REACH conform	Yes
RoHS conform	Yes
Halogen free	No
Impact strength	IK07

Use conditions

Operating temperature	5...60 °C
-----------------------	-----------

temperatur

Ambient temperature	5...60 °C
---------------------	-----------