


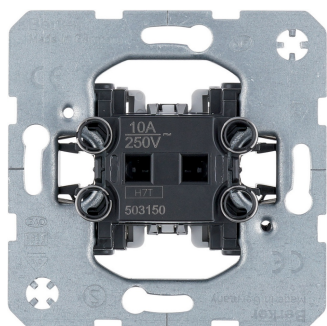

503150

Technische eigenschappen

Spanning

Nominale spanning	250 V
-------------------	-------

Installatie, montage

Gemonteerd op	Inbouwmontage
---------------	---------------

Bediening en signalering

Aantal toetsen	1
----------------	---

Met terugmeldcontact	Nee
----------------------	-----

Type drukknop	Enkele drukknop
---------------	-----------------

Gerelateerde Series	Serie berker B.3, Serie berker B.7, Serie berker K.1, Serie berker K.5, Serie berker Q.1, Serie berker Q.3, Serie berker Q.7, Serie berker R.1, Serie berker R.3, Serie berker R.8, Serie berker S.1
---------------------	--

Relativo Sistema	Serie berker K.x, Serie berker Q.x, Serie berker R.x, Serie berker S.x/B.x
------------------	--

Materiaal

Materiaal	Metaal, Kunststof
-----------	-------------------

Transparant	Nee
-------------	-----

Afmetingen

Diepte	41,60 mm
--------	----------

Inbouwdiepte	19,50 mm
--------------	----------

Inbouwdiepte inbouwdozen	35 mm
--------------------------	-------

Veiligheid

Beschermingsgraad IP	IP20
----------------------	------

Slagvastheid IK	IK07
-----------------	------

Teksten

Aansluitwijze	Met steekklemmen
---------------	------------------

Montagewijze	Geringe inbouwdiepte, Voor schroefbevestiging, Zonder spreidklemmen
--------------	---

Opdruk	Zonder opdruk
--------	---------------

Schakelmodus	Maakcontact
--------------	-------------

Verlichting	Voor verlichtings- en controlecircuit
-------------	---------------------------------------