


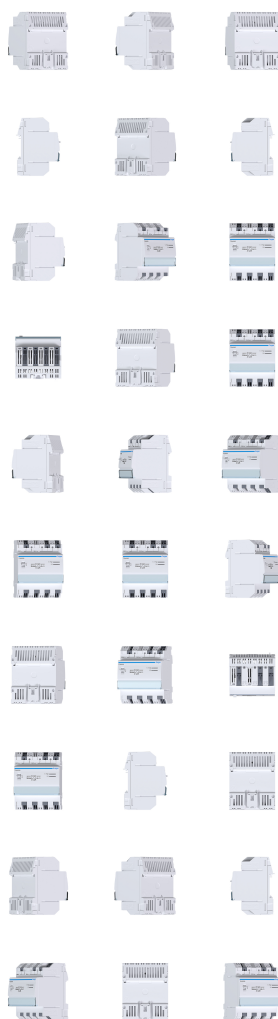

TGA200



## Power supply 24 V DC 1A

### Technical properties

#### Architecture

Bus system EIB

#### Configuration

Number of modules 4

#### Main electrical features

Frequency 50/60 Hz

#### Voltage

Output voltage 24 V DC

Output voltage 24 V

Filtered output voltage 24V +/- 5%

#### Electric current

Output current 1 A

#### Dimensions

Depth of installed product 64 mm

Height of installed product 90 mm

Width of installed product 72 mm

#### Power

Current consumption 150 mA

Power consumed 16 VA

Power consumption (standby) 0.2 W

Total power loss under IN 15 W

#### Measurement

Voltage measurement range 22.8 to 25.2 V

#### Materials

RAL colour RAL 7035 - Light grey

#### Installation, mounting

Modular version Yes

Suitable for front mounting No

#### Connection

Connection cross-sect. flexible conductor 0,75 / 2,5mm<sup>2</sup>

Connection cross-sect. rigid cable 0,75 / 2.5mm<sup>2</sup>

Type of connection	with QuickConnect plug-in terminals
Type of connection	Quickconnect
<b>Equipment</b>	
Short-circuit protected	Yes
<b>Use</b>	
Differentiation characteristic 1 - Sales	with labelling field
<b>Safety</b>	
REACH conform	No
RoHS conform	Yes
Halogen free	No