




WBSEV1

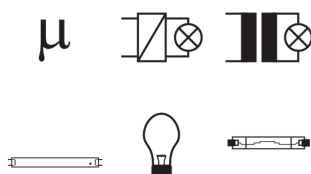

Silhouette 1G LP electronic Switch Vert

Technical properties

Controls and indicators

| | |
|-------------------|---|
| Number of buttons | 1 |
|-------------------|---|

Main electrical features

| | |
|-----------|-------|
| Frequency | 50 Hz |
|-----------|-------|

Dimensions

| | |
|-----------------|--------|
| Insertion depth | 47 mm |
| Height | 117 mm |
| Width | 77 mm |

Power

| | |
|------------------------------------|-------------|
| Dimmable conventional transformers | max. 500 VA |
| Power consumption (standby) | ≤ 0.35 W |
| Electronic transformers | max. 500 W |

Fluorescent bulbs control

| | |
|---------------------------|-------------|
| Compact fluorescent lamps | max. 500 VA |
|---------------------------|-------------|

Incandescent bulbs control

| | |
|--|-------------|
| 230 V incandescent lamps and halogen lamps | max. 1200 W |
|--|-------------|

Installation, mounting

| | |
|-------------------|---------------------|
| Mounting type | flush-mounted |
| Installation mode | for screw fastening |

Connection

| | |
|------------------------|----------------------|
| Screw terminals (max.) | 2 x 1,5/1 x 2,5 mm² |
| Type of connection | with screw terminals |

Scope of delivery

| | |
|-------------------|--|
| Scope of delivery | supplied with standard tapered point 32 mm fixing screws |
|-------------------|--|

Use conditions

| | |
|-------------------------------|-------------|
| Operating temperature | 5...40 °C |
| Storage/transport temperature | -20...60 °C |