




WBSEV4

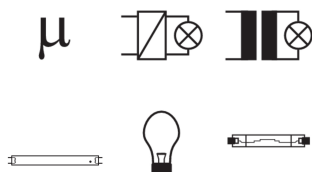

## Silhouette 4G LP electronic Switch Vert

### Technical properties

#### Controls and indicators

Number of buttons	4
-------------------	---

#### Main electrical features

Frequency	50 Hz
-----------	-------

#### Dimensions

Insertion depth	47 mm
Height	117 mm
Width	77 mm

#### Materials

Colour	white
Colour	white

#### Installation, mounting

Mounting type	flush-mounted
Installation mode	for screw fastening

#### Connection

Screw terminals (max.)	2 x 1,5/1 x 2,5 mm <sup>2</sup>
Type of connection	with screw terminals

#### Scope of delivery

Scope of delivery	supplied with standard tapered point 32 mm fixing screws
-------------------	--

#### Safety

REACH conform	Yes
RoHS conform	Yes

#### Use conditions

Operating temperature	5...40 °C
Storage/transport temperature	-20...60 °C