


BF464

Earth leakage add-on block 4P 63A 300mA AC Class

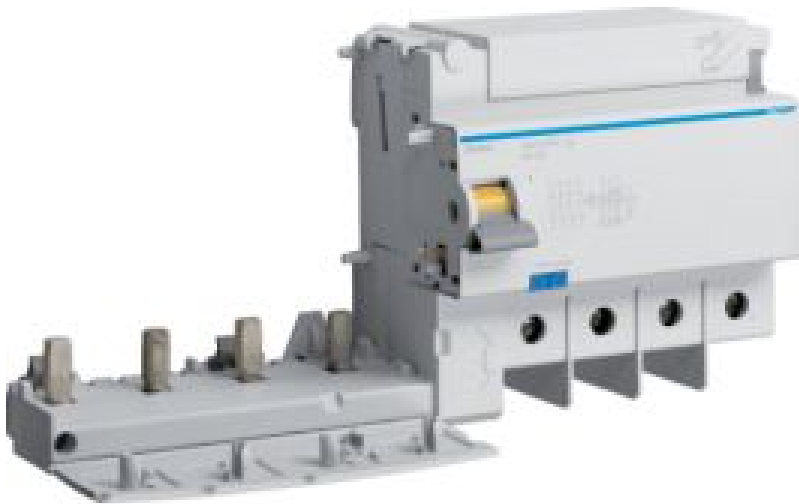

- Architecture
 - Neutral position left
 - Number of poles 4 P
- Main electrical features
 - Frequency 50 Hz
 - Rated current 63 A
- Voltage
 - Rated insulation voltage 500 V
 - Rated impulse withstand voltage 4000 V
- Dimensions
 - Depth of installed product 9.2 cm
 - Height of installed product 7 cm
 - Width of installed product 3.5 cm
- Power
 - Total power loss under IN 35.5 W
- Tripping
 - Short-time delayed tripping

No

- Endurance
 - Electric endurance in number of cycles
2000
 - Number of mechanical operations
1000
- Capacity
 - Number of modules
3
- Installation, mounting
 - Tightening torque
2,8Nm
- Connection
 - Connection cross-sect. flexible conductor
16mm²
 - Connection cross-sect. rigid cable
25mm²
- Standards
 - European directive WEEE
concerned
- Safety
 - Protection index IP
IP20
 - Residual current type
AC
- Use conditions
 - Storage temperature
-25/70 °C