


# Product data sheet

WFSSU83FOPBW

:hager

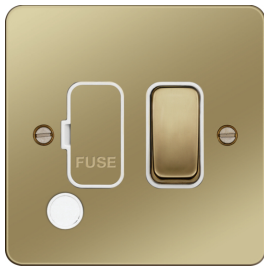

## 13A FCU Switched with Flex Outlet Polished Brass White Insert

### Technical Characteristics

Switch mode	2pole
Frequency	50/60 Hz
Rated current	13 A
Fuse	with ceramic fine fuse F 13A
Depth	30.3 mm
Height	86 mm
Width	86 mm
Colour	brass optics
Material	stainless steel
Imprint	with clear terminal markings
Wiring	with double earth connection
Component	with 2 fixing screws M3.5 x 20 mm
Lighting	without lighting (cannot be illuminated)
Standard	BS 1363-4
Protection	to protect downstream loads
Insert	insert white