


Product data sheet

TXA213N

:hager

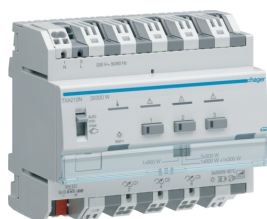

Dimmer 3 channels 300W

Technical Characteristics

Bus system	KNX
Fixing mode	Din-Rail
Indicator lamp	yes
Frequency	50/60 Hz
Supply voltage	30V DC via Bus + 230V AC
Incandescent bulb power	20 W 900 W
Total power loss under IN	5.8 W
Number of modules	6
Colour	stone grey
Connection cross-sect. flexible conductor	0,75 / 2,5mm ²
Connection cross-sect. rigid cable	0,75 / 2.5mm ²
Type of load	universal
Type of connection	quick connect
Protection index IP	IP20
Operating temperature	0 °C 45 °C