


# Product data sheet

TYA628C

**:hager**

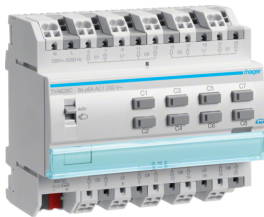

## Output device for 8 shutters or blinds 230V~

### Technical Characteristics

Bus system	KNX
Number of blinds/shutters outputs	8
Fixing mode	REG
Function	with sun shade function with safety functions e.g. for wind, rain, alarm with positioning function for blind and lamella position
Indicator lamp	yes
Bus system radio frequent	No
Frequency	50/60 Hz
Type of supply voltage	AC
Depth	65 mm
Height	90 mm
Dimensions (W x H x D)	90 mm 105 mm 65 mm
Contact rating with 230 V in AC1	1380 W
Total power loss under IN	2 W
Breaking capacity	6A 250V AC1
Number of modules	6
Colour	light grey
RAL colour	RAL 7035 - Light grey
Connection cross-sect. flexible conductor	0,75 / 2,5mm <sup>2</sup>
Connection cross-sect. rigid cable	0,75 / 2.5mm <sup>2</sup>
Type of connection	quick connect
Number of contacts	8
Type of connection	with QuickConnect plug-in terminals
Setting	switching time on change of direction adjustable
Protection index IP	IP20
Operating temperature	45 °C -5 °C
Designation syntax: Main application	230 V
Designation syntax: Core designation/function	Blind actuator