


# WFSS82BSW

13A 2 Gang Double Pole Switched Socket Brushed Steel White Insert

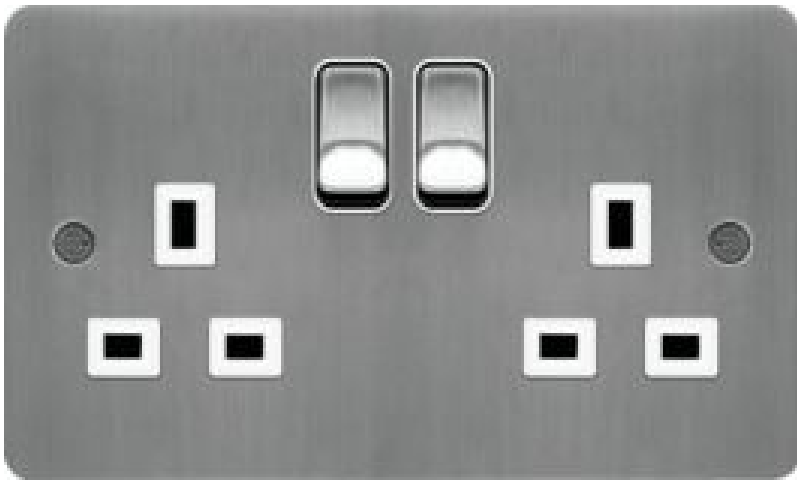

- Architecture
  - Fixing mode  
flush-mounting
- Main electrical features
  - Nominal voltage  
250 V
  - Rated current  
13 A
- Dimensions
  - Depth  
29 mm
  - Height  
86 mm
  - Width  
146 mm
- Frequency
  - Frequency  
50/60 Hz
- Cover, door
  - Cover  
Full cover plate
- Materials
  - Material  
stainless steel
  - Surface appearance  
matt
  - Type of surface treatment

- brushed
- Colour syntax: Colour stainless steel
- Installation, mounting
  - Imprint without imprint
- Connection
  - Type of connection screw
- Cable
  - Wiring with double earth connection
- Scope of delivery
  - Component with 2 fixing screws M3.5 x 20 mm
- Safety
  - Protection index IP IP20
  - Protection Enhanced contact protection
- Use conditions
  - Insert insert white
- Identification
  - Designation syntax: Core designation/function socket outlet