




EE804A

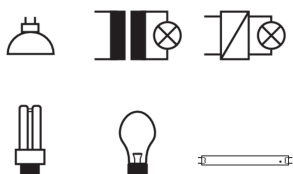

 **IP21**

## Movement detector 360° surface mounted with normally open contact

### Technical characteristics

#### Architecture

Bus system Without

#### Functions

Function can only be used as individual unit

#### Main electrical features

Rated operational voltage  $U_e$  230 V

Frequency 50/60 Hz

#### Dimensions

Height of installed product 50 mm

Width of installed product 105.5 mm

#### Power supply

Supply voltage 230 V +10% / -15%

#### Detection

Detection angle 360 °

#### Materials

Colour white

Material plastic

#### Lighting control

Brightness measurement range 5 / 1000 Lux

#### Installation, mounting

Mounting type surface-mounted

Maximum Mounting Height 4 m

#### Connection

Number of contacts 1

Type of connection with screw terminals

#### Settings

Setting with potentiometers for setting the response brightness and delay time without dismantling

#### Scope of delivery

Component with fitting material

#### Equipment

Angle of horizontal detection

360 °

---

**Safety**

Protection class

isol.class II

---

**Use conditions**

Operating temperature

-5...45 °C