




EE804A

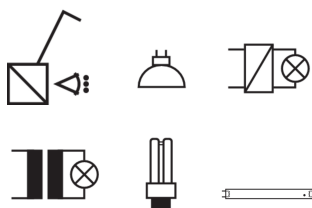

IP21

Movement detector 360° surface mounted with normally open contact

Technical characteristics

Architecture

Fixing mode surface-mounting

Functions

Function can only be used as individual unit

Main electrical features

Rated operational voltage U_e 230 V

Frequency 50/60 Hz

Dimensions

Height of installed product 50 mm

Width of installed product 105.5 mm

Power supply

Supply voltage 230 V +10% / -15%

Detection

Detection angle 360 °

Materials

Colour white

RAL colour RAL 9001 - Cream

Material plastic

Lighting control

Brightness measurement range 5 / 1000 Lux

Installation, mounting

Mounting type surface-mounted

Maximum Mounting Height 4 m

Connection

Number of contacts 1

Type of connection with screw terminals

Scope of delivery

Component with fitting material

Equipment

Angle of horizontal detection 360 °

Safety

Protection index IP	IP21
Protection class	isol.class II

Use conditions

Operating temperature	-5...45 °C
-----------------------	------------