


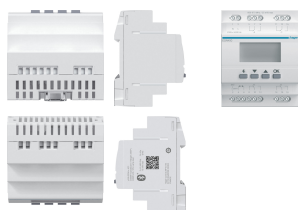

EGN400



Multi-function time switch 4 channels bluetooth

Technical characteristics

Main electrical features

Rated operational voltage U_e	230 V
Frequency	50/60 Hz
Nominal voltage	230 V
Type of supply voltage	AC

Dimensions

Depth of installed product	61.6 mm
Height of installed product	90 mm
Width of installed product	70 mm

Power

Power consumed	0.71 VA
Power consumption (operation)	500 mW

Lighting control

Brightness measurement range	1 / 2000 Lux
------------------------------	--------------

Fluorescent bulbs control

Max. power with fluorescent parallel lamps	400 W
Max. power fluo. duo lamp comp. series	1000 W

Incandescent bulbs control

Max. power with incandescent lamps	2300 W
------------------------------------	--------

Installation, mounting

Tightening torque	0.5Nm
-------------------	-------

Connection

Connection cross-sect. flexible conductor	0.2 / 2.5mm ²
Connection cross-sect. rigid cable	0,2 / 4mm ²
Type of connection	with screw
Number of contacts	4
Type of contacts	1 changeover
Type of connection	with screw terminal

Settings

Shortest switching time	1 mn
-------------------------	------

Equipment

Type of programmable thermostat	Digital
---------------------------------	---------

Number of channels	4
Supply failure reserve	10 years

Use conditions

Working accuracy	60
------------------	----