




EVN004

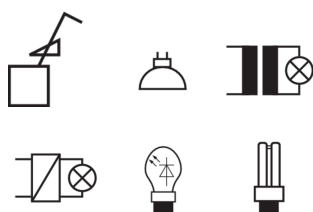

**IP20**

## Remote Control Dimmer universal 500W

### Technical characteristics

#### Architecture

Fixing mode Din-Rail

#### Main electrical features

Rated operational voltage  $U_e$  230 V

Frequency 50/60 Hz

#### Fuse

Fuse with electronic short-circuit and overload protection

#### Dimensions

Depth of installed product 62 mm

Height of installed product 85 mm

Width of installed product 35 mm

#### Power

Halogen switching capacity 230V 500 W

Power consumed 4.5 W

Power consumption (operation) 4.5 W

Incandescent bulb power 500 W

Total power loss under IN 0.2 W

#### Materials

RAL colour RAL 9001 - Cream

Surface appearance matt

#### Incandescent bulbs control

Max. power with incandescent lamps 500 W

#### Installation, mounting

Mounting type din-Rail

#### Connection

Connection cross-sect. flexible conductor 1 / 6mm<sup>2</sup>

Connection cross-sect. rigid cable 1 / 6mm<sup>2</sup>

Type of load universal

Type of connection with screw

Type of connection with screw terminals

#### Settings

Setting

setting of comfort functions (1...4) via adjusting  
wheel ; Reset of settings for special functions

---

**Safety**

Protection index IP

IP20

---

**Use conditions**

Operating temperature

-20...50 °C