




EVN012

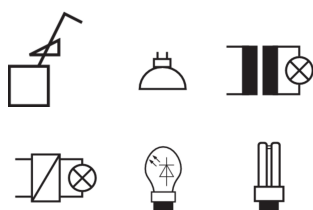

IP20

Universal Remote Control Dimmers 300W Comfort

Technical characteristics

Architecture

Fixing mode	Din-Rail
-------------	----------

Main electrical features

Rated operational voltage Ue	230 V
Frequency	50/60 Hz

Dimensions

Depth of installed product	65 mm
Height of installed product	90 mm
Width of installed product	17.5 mm

Power

Halogen switching capacity 230V	300 W
Power consumed	2.1 W
Power consumption (operation)	2.1 W
Incandescent bulb power	300 W
Total power loss under IN	0.2 W

Materials

RAL colour	RAL 9001 - Cream
Surface appearance	matt

Incandescent bulbs control

Max. power with incandescent lamps	300 W
------------------------------------	-------

Installation, mounting

Mounting type	din-Rail
---------------	----------

Connection

Type of load	universal
Type of connection	with screw terminals

Safety

Protection index IP	IP20
---------------------	------

Use conditions

Operating temperature	-10...45 °C
-----------------------	-------------