




HCW630AR

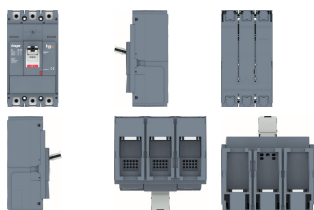

## Load Break Switch Disconnecter h3+ P630 3P 630A FTC

### Technical characteristics

#### Electric current

|                                                              |         |
|--------------------------------------------------------------|---------|
| Rated current                                                | 630 A   |
| Rated short-time withstand current I <sub>cw</sub> IEC 60947 | 7.60 kA |

#### Architecture

|                           |        |
|---------------------------|--------|
| Number of poles           | 3      |
| Control/operation element | Toggle |

#### Voltage

|                                                  |         |
|--------------------------------------------------|---------|
| Rated insulation voltage U <sub>i</sub>          | 800 V   |
| Rated impulse withstand voltage U <sub>imp</sub> | 8,000 V |

#### Frequency

|           |            |
|-----------|------------|
| Frequency | 50 - 60 Hz |
|-----------|------------|

#### Functions

|           |        |
|-----------|--------|
| Trip unit | Switch |
|-----------|--------|