




TRE400

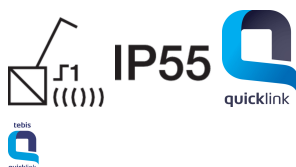

## Module 1 input + 1 output, 10A, IP55, KNX radio

### Technical characteristics

#### Architecture

Bus system	KNX
Number of blinds/shutters outputs	0
Fixing mode	surface-mounting

#### Controls and indicators

Indicator lamp	yes
----------------	-----

#### Connectivity

Bus system radio frequent	Yes
---------------------------	-----

#### Main electrical features

Type of supply voltage	AC
------------------------	----

#### Voltage

Operating voltage	230 V AC
-------------------	----------

#### Dimensions

Height	35 mm
Width	85 mm

#### Reach distance

Max. transmission range	30m in house / 100m free field
-------------------------	--------------------------------

#### Materials

Surface appearance	matt
--------------------	------

#### Connection

Type of connection	with screw-in lift terminals
--------------------	------------------------------

#### Equipment

Number of channels	1
--------------------	---

#### Use conditions

Operating temperature	-10...55 °C
-----------------------	-------------