




TYA661BN

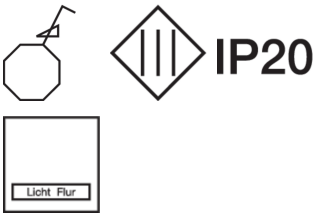

Dimmer 1 channel 600W

Technical characteristics

Controls and indicators

Indicator lamp	yes
----------------	-----

Connectivity

Bus system radio frequent	No
---------------------------	----

Main electrical features

Frequency	50/60 Hz
-----------	----------

Power

Incandescent bulb power	600 W
Total power loss under IN	320 mW
Power dissipation per coil	180 mW

Connection

Type of load	universal
Type of connection	quick connect

Equipment

Dimming principle	phase cut-on or cut-off according to load type, self-learning
-------------------	---

Safety

Protection index IP	IP20
---------------------	------

Use conditions

Operating temperature	-5...45 °C
-----------------------	------------