


Enclosed MCCB (63A - 125A)

Characteristics	
Series	JG**
MCCB	63A to 125A MCCB
MCCB + RCCB Add on block	63A & 100A
Voltage rating in AC	240 / 415 V
IP Protection	IP3X
Enclosure body type	Steel
Enclosure paint type	Powder coat Grey white BS 4800 00A01
Terminal Connection capacity	
maximum terminal capacity	95mm ²
Enclosure earth stud	M8
Installation	
Mounting	Wall

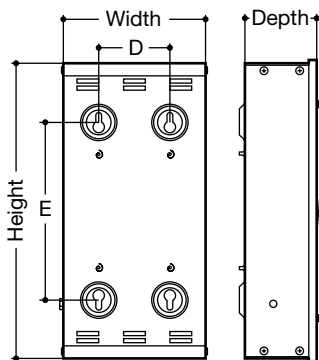

	Dimensions (mm)			Fixing centres	
	Height	Depth	Width	D	E
JG25BM	420	106	200	100	249
JG26BM	420	106	200	100	249
JG27BM	420	106	200	100	249
JG27BR	420	106	300	200	249
JG28BM	420	106	200	100	249
JG29BM	420	106	200	100	249
JG30BM	420	106	200	100	249
JG31BM	420	106	200	100	249
JG32BM	420	106	200	100	249
JG33BM	420	106	200	100	249
JG30BR	420	106	300	200	249
JG34BS	420	106	200	100	249
JG35BS	420	106	200	100	249