



Invicta 3 JN2 Pluggable Meter Kit - JN201PM

Instructions/Data Sheet


Sales Service Centre: 01952 675 612
Sales Service Centre Faxline: 01952 675 645

Technical Service Centre: 01952 675 689
Technical Service Centre Faxline: 01952 675 557


www.hager.co.uk

Components in this kit:


- Meter, CT and loom assembly
- 3 x M4 meter bracket fixings
- 4 x CT bracket fixings
(2 x M4, 2 x 4mm self taper)
- CT 'Warning' label

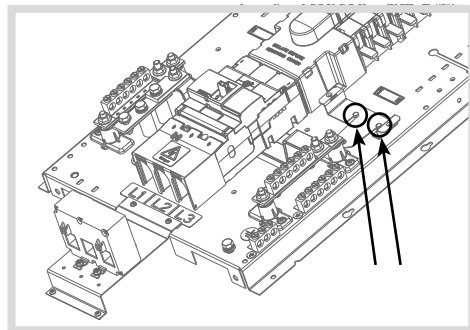


Fit 2 x meter bracket M4 fixings into the chassis, allowing clearance for the bracket slots

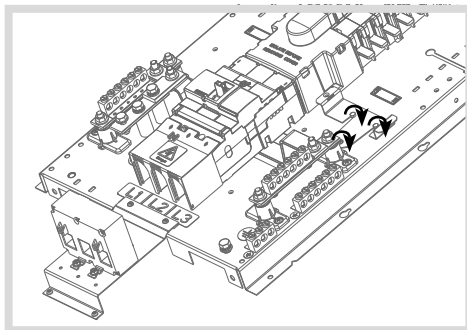

Fit the meter bracket, slotting onto the fixings (1). Use the third M4 fixing to secure the bracket (2).

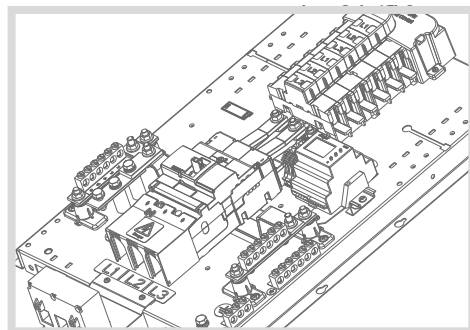

Fit DIN rail/meter sub-assembly to DIN rail support bracket (M5 fixings)

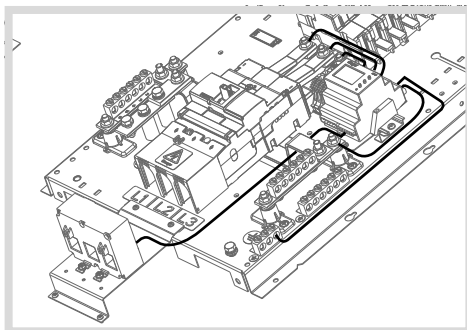

Fit lower CT pack to pan assembly using 2 x M4 m/c screws and 2x self tapping screws. Connect power loom cables to lower busbar stack (L1, L2, L3) and neutral/earth. M8 electrical connections 13Nm. Plug RJ45 lead into CT & meter.